

# Cole-Parmer® Dissecting Instruments

Fit your application and your budget

**NEW**



– Two grades available to suit your requirements

**Standard-grade** instruments are manufactured from stainless steel; hardened, tempered, and polished for a high-priced finish without the added cost. These instruments are well-suited for less critical applications. **Autoclavable.**


**Premium-grade** instruments feature the highest quality stainless steel, crafted to the most exacting standards, to meet the most demanding needs. Precision cutting and holding surfaces, ratcheting lock mechanisms, and nonglare finish are ideal for critical procedures. **Autoclavable.**

## Scissors



Type	Description	Length		Standard-grade		Premium-grade	
		in.	cm	Catalog number	Price	Catalog number	Price
Dissecting scissors	Sharp/sharp point/straight	5½	13.9	<a href="#">GH-10818-00</a>		<a href="#">GH-10821-00</a>	
	Sharp/blunt point/straight			<a href="#">GH-10818-01</a>		<a href="#">GH-10821-01</a>	
SuperCut scissors	Micro-serrated/ blunt/blunt/straight	5½	13.9	—	—	<a href="#">GH-10821-02</a>	
	Micro-serrated/ blunt/blunt/curved			—	—	<a href="#">GH-10821-03</a>	
Mayo dissecting scissors	Blunt/blunt point/straight	5½	13.9	<a href="#">GH-10818-02</a>		<a href="#">GH-10821-04</a>	
Metzenbaum dissecting scissors	Blunt/blunt point/curved			<a href="#">GH-10818-03</a>		<a href="#">GH-10821-05</a>	
Iris scissors	Straight	4½	11.4	<a href="#">GH-10818-04</a>		<a href="#">GH-10821-06</a>	
				<a href="#">GH-10818-05</a>		<a href="#">GH-10821-07</a>	
				<a href="#">GH-10818-06</a>		<a href="#">GH-10821-08</a>	
Microscissors	Straight	4	10.1	<a href="#">GH-10818-07</a>		<a href="#">GH-10821-09</a>	
	Curved						


## Hemostatic Forceps

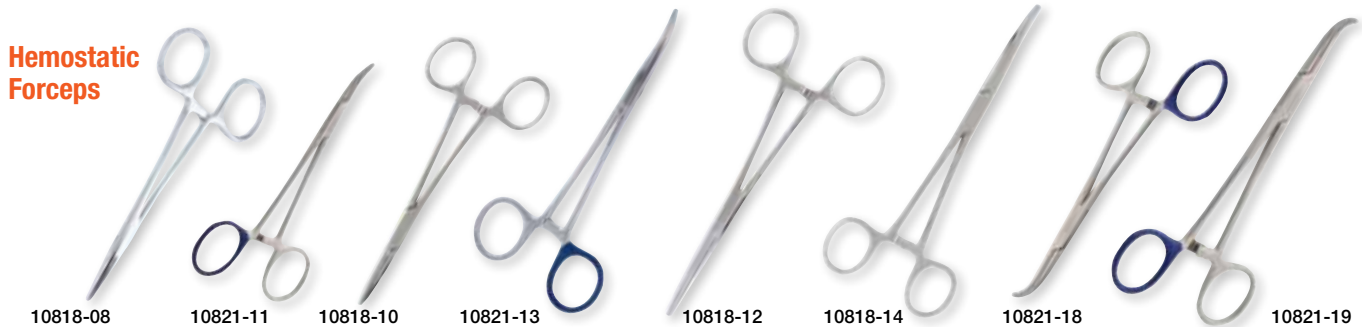

Type	Description	Length		Standard-grade		Premium-grade	
		in.	cm	Catalog number	Price	Catalog number	Price
Halsted mosquito forceps	Straight	5	12.7	<a href="#">GH-10818-08</a>		<a href="#">GH-10821-10</a>	
	Curved			<a href="#">GH-10818-09</a>		<a href="#">GH-10821-11</a>	
Kelly forceps	Straight	5½	13.9	<a href="#">GH-10818-10</a>		<a href="#">GH-10821-12</a>	
	Curved			<a href="#">GH-10818-11</a>		<a href="#">GH-10821-13</a>	
Rochester Pean forceps	Straight	6¼	15.9	<a href="#">GH-10818-12</a>		<a href="#">GH-10821-14</a>	
		7¼	18.4	<a href="#">GH-10818-13</a>		<a href="#">GH-10821-15</a>	
Rochester Pean forceps	Curved	6¼	15.9	<a href="#">GH-10818-14</a>		<a href="#">GH-10821-16</a>	
		7¼	18.4	<a href="#">GH-10818-15</a>		<a href="#">GH-10821-17</a>	
Baby Mixer forceps	Extra-delicate, fully curved	5½	13.9	—	—	<a href="#">GH-10821-18</a>	
Mixer forceps	Right angle	6¼	15.9	<a href="#">GH-10818-16</a>		<a href="#">GH-10821-19</a>	
Kantrowitz forceps	Delicate, right angle	7¼	18.4	—	—	<a href="#">GH-10821-20</a>	

## Needle Holders

Type	Length		Standard-grade		Premium-grade	
	in.	cm	Catalog number	Price	Catalog number	Price
Mayo-Hegar	5	12.7	<a href="#">GH-10818-17</a>		<a href="#">GH-10821-21</a>	
	7	15.2	<a href="#">GH-10818-18</a>		<a href="#">GH-10821-22</a>	
Olsen-Hegar	5	12.7	<a href="#">GH-10818-19</a>		<a href="#">GH-10821-23</a>	
	7	15.2	<a href="#">GH-10818-20</a>		<a href="#">GH-10821-24</a>	

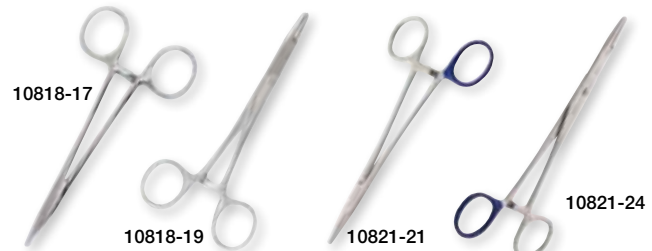

**Warning**—These products are not approved or intended for, and should not be used for, medical, clinical, surgical or other patient oriented applications.