

Thermo Scientific™ Nalgene™ Rectangular Carboys, PP

Maintain sample integrity—
autoclavable

- No dead space—rectangular design does not waste space
- Leakproof for better handling
- Easy transport via steel handle
- Withstand temperatures to 248°F (120°C)



Buy More...Save More!

\$ 20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases

Liters (gallons)	Cap size	Catalog number	Qty/pk	Price/pk
Rectangular carboys				
9 (2)	100 mm	GH-06082-60	1	
20 (5)	100 mm	GH-06082-70	1	
Rectangular carboys with spigot				
9 (2)	100 mm	GH-06082-80	1	
20 (5)	100 mm	GH-06082-90	1	

[GH-06070-22](#) Replacement spigot, PP

[GH-63000-16](#) Replacement cap; PP, 100 mm. Pack of 12

Thermo Scientific™ Nalgene™ Rectangular Carboys, PC

Don't lose sight of your solution

- Transparent, polycarbonate (PC) carboys allow easy viewing of solutions
- Easily transport carboys with steel handle
- Dispense samples quickly with spigot models
- Autoclavable



Buy More...Save More!

\$ 20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases

Liters (gallons)	Cap size	Catalog number	Qty/pk	Price/pk
Rectangular carboy				
20 (5)	100 mm	GH-06084-70	1	
Rectangular carboys with spigot				
9 (2)	100 mm	GH-06084-80	1	
20 (5)	100 mm	GH-06084-90	1	

[GH-06070-22](#) Replacement spigot, PP

[GH-63000-16](#) Replacement cap; PP, 100 mm. Pack of 12

Thermo Scientific™ Nalgene™ Rectangular Carboys, HDPE

Don't waste valuable bench space

- Space-saving design for no dead area like traditional round carboys
- Leakproof high-density polyethylene (HDPE) for safe transport
- Liter/gallon graduations for easy volume determination



Carboys with quick-action spigots accept 5/8" ID tubing, come with adapters for 1/4" to 1/2" ID tubing, and feature an integrally molded threaded boss. Aspirator carboys feature integral tubulation for 1/2" ID tubing.

Buy More...Save More!

\$ 20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases


Liters (gallons)	Cap size	Catalog number	Qty/pk	Price/pk
Rectangular carboys				
9 (2)	100 mm	GH-06032-20	1	
20 (5)	100 mm	GH-06032-50	1	
Rectangular carboys with spigot				
9 (2)	100 mm	GH-06066-20	1	
20 (5)	100 mm	GH-06066-50	1	
Rectangular carboys with tubulation				
20 (5)	100 mm	GH-06082-50	1	

Thermo Scientific™ Nalgene™ Filling/Venting Caps, PP

Quick and easy aseptic liquid transfer

Filling/Venting Caps have thermoplastic elastomer (TPE) gaskets to allow aseptic liquid transfer. Include 6" (15 cm) and 30" (76 cm) lengths of platinum-cured silicone tubing. Autoclavable.

Fitting Kits include two PP fittings, two acetal nuts, two silicone gaskets, thermoplastic elastomer (TPE) port cap, instructions, and template. Autoclavable.

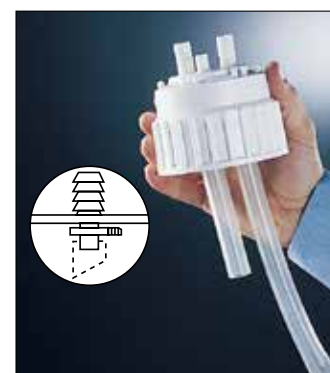

Buy More...Save More!

\$ 20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases

Tubing ID	Ports	Cap size	Catalog number	Qty/pk	Price/pk
Filling/venting caps					
1/2"	2 tubing, 1 venting	83B	GH-06258-00	1	
1/4"		53B	GH-06258-10	1	
1/4"		83B	GH-06258-20	1	
Barbed bulkhead fitting kits					
1/4"	—	—	GH-06259-10	2	
1/2"	—	—	GH-06259-00	2	