

## Cole-Parmer® Specialty and Support Clamps (continued)



08043-22

F



08043-30

### F. Thermometer Clamps

Double-sided opening mechanism allows jaws to spread evenly and easily to secure delicate glassware such as glass thermometers. Swivel model 08043-22 allows the clamp to turn 360°. Both clamps have an integral connector.

Type	Material	Grip range	Arm length	Overall length	Catalog number	Price
Swivel	Nickel-plated zinc	0.24" to 0.32" (6 to 8 mm)	—	6.24" (15.8 cm)	<a href="#">GH-08043-22</a>	
Extension	zinc	0.24" to 0.47" (6 to 12 mm)	5" (12.7 cm)	8.27" (21 cm)	<a href="#">GH-08043-30</a>	



08047-04

G




08129-91

### G. Swivel Clamps

Ideal for cylindrical-shaped labware. Swivel action allows a full 360° adjustment. Clamps have integral connector and include both slip-on vinyl and fiberglass sleeves.

Type	Material	Size	Grip range	Overall length	Catalog number	Price
Two-prong, single adjustment	Nickel-plated zinc	Medium	0 to 3" (0 to 76 mm)	6.06" (16.3 cm)	<a href="#">GH-08047-02</a>	
		Large	0 to 3.74" (0 to 95 mm)	7.125" (18 cm)	<a href="#">GH-08047-04</a>	
Three-prong, dual adjustment	Nickel-plated zinc	Medium	0 to 3" (0 to 76 mm)	6.06" (16.3 cm)	<a href="#">GH-08129-92</a>	
		Stainless steel	Medium	0 to 2.72" (0 to 69 mm)	6.06" (16.3 cm)	<a href="#">GH-08047-06</a>
Three-prong, dual adjustment	Stainless steel	Medium	0 to 2.72" (0 to 69 mm)	6.06" (16.3 cm)	<a href="#">GH-08129-91</a>	

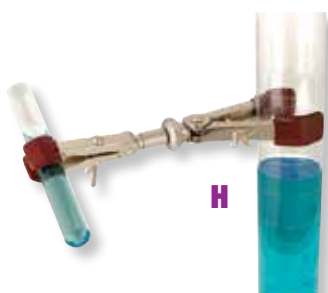

H

### H. Double-Jaw Swivel Clamp

This unique clamp features a jaw on each side of the clamp and swivel action that allows for a 360° adjustment radius. The clamp features a medium two-prong jaw on one end and a larger two-prong jaw on the other end. Use to hold two different-sized objects, or to have one side attached to a stationary support and the other side supporting an object. Both slip-on vinyl and fiberglass sleeves are included.

Type	Material	Grip range	Prong width	Overall length	Catalog number	Price
Medium two-prong jaw and large two-prong jaw	Nickel-plated zinc	Medium jaw: 0 to 3" (0 to 76 mm); large jaw: 0 to 3.74" (0 to 95 mm)	0.91" (23 mm)	8.74" (22.2 cm)	<a href="#">GH-08027-12</a>	



I

### I. Chain Clamps

These clamps firmly hold circular and irregularly shaped apparatus. Feature a quick slip-on-chain connection, a large easy-to-turn adjustment knob, and an integral connector. Both slip-on vinyl and fiberglass sleeves are included.

**Note:** To install clamps to lab frames, support stands, and other apparatus, you will need to purchase a connector or holder that accepts a 0.5" (12.7 mm) dia rod; order separately on pages 138–139.

Material	Size	Grip range	Arm length	Overall length	Catalog number	Price
Nickel-plated zinc	Small	1.38" to 6.69" (35 to 170 mm)	5" (12.7 cm)	7.4" (18.8 cm)	<a href="#">GH-08047-32</a>	
	Large	1.38" to 11.02" (35 to 280 mm)	5" (12.7 cm)	8.11" (20.6 cm)	<a href="#">GH-08047-34</a>	
	Large, extended	1.38" to 11.02" (35 to 280 mm)	12" (30.5 cm)	15.12" (38.4 cm)	<a href="#">GH-08047-36</a>	
Stainless steel	Large	1.38" to 11.02" (35 to 280 mm)	5" (12.7 cm)	8.11" (20.6 cm)	<a href="#">GH-08129-89</a>	



J

### J. Electrode Support Clamp

Ideal for potentiometric titrations, this clamp is designed to suspend your electrode at the desired level and angle. Features an integral connector.

Material	Overall length	Catalog number	Price
Nickel-plated zinc	7" (17.8 cm)	<a href="#">GH-08027-06</a>	

See previous page for more...