

Wearwell® PermaTack Tacky Mats

Prevent debris and bacteria from entering sterile areas

- Reusable and economical—replace your multilayer adhesive mats
- Permanently tacky surface removes particles off shoes and wheels; contaminants remain trapped until mat is cleaned
- Removes 98 to 100% of particles if each foot touches the mat three times
- Regenerate the tack by simply cleaning the mat and allowing it to dry
- Adhesive backing allows easy installation and prevents mat movement
- Surface is static dissipative; RTT = 1×10^8 to 1×10^{10} ohms



Size (W x L)	Color	Thickness	Catalog number	Price
27" x 48" (69 x 122 cm)	Blue	1/8" (0.32 cm)	GH-84580-20	
27" x 72" (69 x 183 cm)			GH-84580-21	
36" x 54" (91 x 137 cm)			GH-84580-22	
27" x 10 ft (69 cm x 3 m)	Blue	1/8" (0.32 cm)	GH-84580-23	
54" x 10 ft (137 cm x 3 m)			GH-84580-24	

Adhesive Roll Mops

Quickly clean surfaces of dust and lint

- Adhesive traps dirt and removes it easily
- Simply peel back layer to expose clean sheet
- Perforated rolls for easy tearing—each roll contains 20 sheets



Roll mop with 7 ft. telescopic handle 09411-60



Handheld roll mop 09411-50


Find even more online!
Go to ColeParmer.com to search more than 100,000 products.

Description	Roll mops			Refills	
	Size (W)	Cat. no.	Price	Cat. no.	Price
Handheld	3" (7.6 cm)	GH-09411-40		GH-09411-43	
	9" (22.9 cm)	GH-09411-50		GH-09411-53	
Telescopic handle	18" L x 9" W (45.7 x 22.9 cm)	GH-09411-60		GH-09411-63	

Contec® EasySat™ Bucketless Floor Mop

No more buckets and wringers

- Easily clean up to 500 ft² with just one tank of solution
- Dispense only what you need with easy trigger mechanism
- All hardware is autoclavable at 121°C for 30 minutes
- Mop heads are sold separately
- Sterile mop heads are gamma irradiated to 10⁻⁶ Sterility Assurance Level per AAMI/ISO 11137:2006 guides

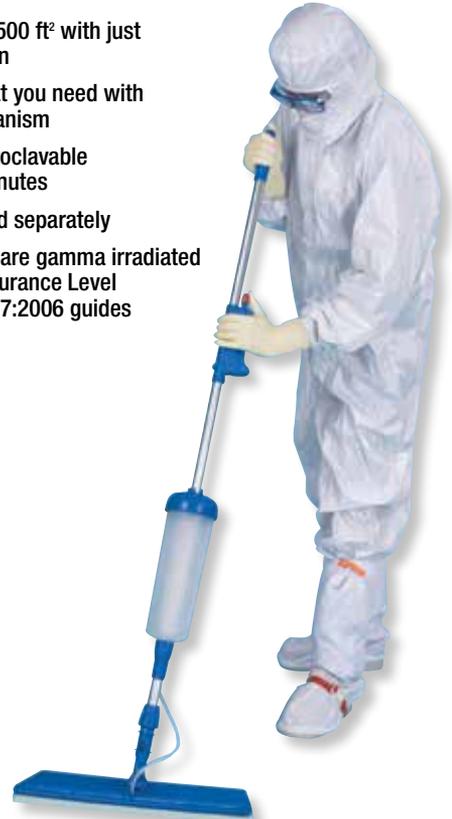

Description	Qty/pk	Catalog number	Price/pk
Bucketless floor mop, 21 1/2" x 57 1/2" x 4 1/4" (54.6 x 146 x 10.8 cm)	1	GH-09411-30	
Mop head	32	GH-09411-31	
Mop head, textured	32	GH-09411-35	
Mop head, sterile	28	GH-09411-36	
Mop head, textured and sterile	28	GH-09411-37	