

## Microflex® Cleanroom Gloves

### Eliminate contamination

- Low residues including particulates, ionic extractables, and nonvolatiles
- Textured surface for better gripping
- Latex-free to eliminate adverse reactions
- Surface resistivity of 10<sup>11</sup> ohm/square for static decay
- Ambidextrous




**Compliance:**  
ISO Class 4 or 5

Size	Length	Thickness	Qty/bg	Catalog number	Price per bag	
					1 bg	10 bg
<b>Latex ISO Class 4 cleanroom gloves</b>						
Small	12" (30 cm)	6.3 mil	100	<a href="#">GH-86313-35</a>		
Medium				<a href="#">GH-86313-36</a>		
Large				<a href="#">GH-86313-37</a>		
X-large				<a href="#">GH-86313-38</a>		
<b>Nitrile ISO Class 4 cleanroom gloves</b>						
Small	12" (30 cm)	5.2 mil	100	<a href="#">GH-86313-45</a>		
Medium				<a href="#">GH-86313-46</a>		
Large				<a href="#">GH-86313-47</a>		
X-large				<a href="#">GH-86313-48</a>		
<b>Latex ISO Class 5 cleanroom gloves</b>						
Small	12" (30 cm)	6.3 mil	100	<a href="#">GH-86313-15</a>		
Medium				<a href="#">GH-86313-16</a>		
Large				<a href="#">GH-86313-17</a>		
X-large				<a href="#">GH-86313-18</a>		
<b>Nitrile ISO Class 5 cleanroom gloves</b>						
Small	12" (30 cm)	5.2 mil	100	<a href="#">GH-86313-25</a>		
Medium				<a href="#">GH-86313-26</a>		
Large				<a href="#">GH-86313-27</a>		
X-large				<a href="#">GH-86313-28</a>		

## QRP® Vinyl Cleanroom Gloves

### Don't contaminate samples

- Latex-free, PVC copolymer is naturally antistatic
- Micro-textured surface for better gripping
- Ambidextrous
- Packed 100 gloves per polybag

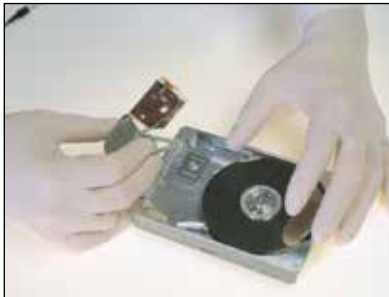

**Compliance:**  
ISO Class 5, USDA,  
and IEST-RP-CC-005.2

Size	Length	Thickness	Qty/bg	Catalog number	Price per bag	
					1 bg	10 bg
Medium	12" (30 cm)	6 mil	100	<a href="#">GH-86580-21</a>		
Large				<a href="#">GH-86580-22</a>		
X-large				<a href="#">GH-86580-23</a>		

## Best® Butyl II Gloves

### Stay safe during clean-ups

- Non-bulky and non-restrictive for easier handling
- Excellent chemical resistance
- Long, 14" gloves for added protection
- Ideal for use with hazmat suits

**Compliance:** ASTM F739.



Size	Description	Catalog number	Price per pair	
			1 pr	12 pr
Medium	Smooth gloves, 14-mil thick	<a href="#">GH-86357-01</a>		
Large		<a href="#">GH-86357-02</a>		
X-large		<a href="#">GH-86357-04</a>		
Medium	Textured gloves, 14-mil thick	<a href="#">GH-86357-11</a>		
Large		<a href="#">GH-86357-12</a>		
X-large		<a href="#">GH-86357-13</a>		
Medium	Heavyweight smooth gloves, 30-mil thick	<a href="#">GH-86357-20</a>		
Large		<a href="#">GH-86357-21</a>		
X-large		<a href="#">GH-86357-22</a>		

## Best® Viton® Gloves

### Get flexible, heavy-duty protection

- Superior resistance to PCBs, as well as chlorinated and aromatic solvents



Size	Length	Thickness	Catalog number	Price per pair	
				1 pr	12 pr
Small	14" (35 cm)	12 mil	<a href="#">GH-86288-20</a>		
Medium			<a href="#">GH-86288-21</a>		
Large			<a href="#">GH-86288-22</a>		
X-large			<a href="#">GH-86288-23</a>		
Large	14" (35 cm)	30 mil	<a href="#">GH-86288-32</a>		
X-large			<a href="#">GH-86288-33</a>		