

## Bausch & Lomb® Hastings Triplet Measuring Magnifiers

No distortion—just sharp images

- Get optical precision with a double convex element and two concave elements
- Illuminate magnified area through transparent body
- Block glare with black-coated lens sides



Magnification	Focal distance	Viewing area	Catalog number	Price
7x	1.5" (3.9 cm)	0.78" (19.8 mm)	<a href="#">GH-03882-10</a>	
10x	1.0" (2.5 cm)	0.62" (15.8 mm)	<a href="#">GH-03882-50</a>	

## Bausch & Lomb® Hastings Triplet Magnifiers

Get microscope quality magnification—up to 20x

- No more distortion—three optical lenses are bonded forming a "Hastings Triplet"
- Lens is recessed for protection from damage




Swing-away case also serves as a handle.

Magnification	Focal distance	Viewing area	Catalog number	Price
7x	1.5" (3.9 cm)	0.78" (19.8 mm)	<a href="#">GH-03882-20</a>	
10x	1.0" (2.5 cm)	0.62" (15.8 mm)	<a href="#">GH-03882-22</a>	
14x	0.8" (2.0 cm)	0.49" (12.5 mm)	<a href="#">GH-03882-24</a>	
20x	0.5" (1.3 cm)	0.32" (8.3 mm)	<a href="#">GH-03882-26</a>	

## Bausch & Lomb® Handheld Magnifiers

Get larger viewing area

- Stabilizing edge helps steady lens without putting fingers on lens
- Get better detail with higher power lens insert on round lenses

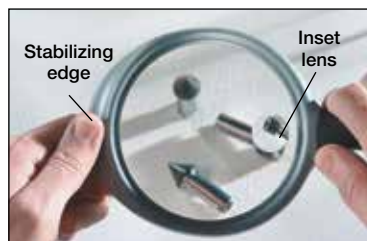

Magnification	Viewing area	Inset power	Catalog number	Price
2x (8 diopter)	3 1/4" round	4x	<a href="#">GH-03887-00</a>	
	4" round	6x	<a href="#">GH-03887-02</a>	
	5" round	4x	<a href="#">GH-03887-04</a>	
	2" x 4" rectangular	—	<a href="#">GH-46202-00</a>	

## Bausch & Lomb® Folding Pocket Magnifiers

Plastic case protects the lens

- Plastic swing-away case doubles as a handle during use
- Combine lenses in multi-lens models for different magnification power



Number of lenses	Magnification	Focal distance	Catalog number	Price
1	4x	2.5" (6.4 cm)	<a href="#">GH-03882-15</a>	
2	4x to 9x	2.5" to 1.1" (6.4 to 2.8 cm)	<a href="#">GH-03882-17</a>	
3	5x to 20x	2.0" to 0.5" (5.1 to 1.3 cm)	<a href="#">GH-03882-19</a>	

## Bausch & Lomb® Lenscope® Magnifier

No dark imaging

- Illuminate items with two angled light sources
- Require two AA batteries, sold separately



Magnification	Focal distance	Viewing area	Catalog number	Price
10x	1.0" (2.5 cm)	0.62" (15.8 mm)	<a href="#">GH-03882-40</a>	

[GH-09376-01](#) Batteries, AA. Pack of 4

## LED Magnifiers

No more eye strain

- Larger viewing area and brighter LED light for better sample viewing
- Handheld models are ideal for field use
- Stand magnifiers can be handheld or a table slide magnifier
- Stand magnifiers require 3 AA batteries, handheld magnifiers require 3 AAA batteries (order separately)



Magnification	Viewing area	Catalog number	Price
<b>Handheld LED magnifiers</b>			
7x	2.0" (50 mm)	<a href="#">GH-03889-80</a>	
8x	1.3" (35 mm)	<a href="#">GH-03889-82</a>	
10x	1.3" (35 mm)	<a href="#">GH-03889-84</a>	
12x	1.3" (35 mm)	<a href="#">GH-03889-86</a>	
14x	1.3" (35 mm)	<a href="#">GH-03889-88</a>	
<b>Stand LED magnifiers</b>			
3x	3.0" (75 mm)	<a href="#">GH-03889-70</a>	
7x	2.0" (50 mm)	<a href="#">GH-03889-72</a>	
8x	1.3" (35 mm)	<a href="#">GH-03889-74</a>	

[GH-09376-00](#) Batteries, AAA. Pack of 12

[GH-09376-01](#) Batteries, AA. Pack of 4

## Bausch & Lomb® Magna Visor Magnifier

Keep your hands free

- Visor fits easily over glasses, making it ideal for keeping hands free for better inspection
- Fits all head sizes with adjustable band
- Interchangeable lenses for different focal lengths—magnifier includes all three; order additional separately



Visor tilts up when not in use.

Focal distance	Magnification	Magnifier		Replacement Lens	
		Catalog number	Price	Catalog number	Price
12" (305 mm)	3.0x	GH-03886-02	00.00	<a href="#">GH-03886-01</a>	
8" (203 mm)	3.0x			<a href="#">GH-03886-11</a>	
6" (152 mm)	3.0x			<a href="#">GH-03886-21</a>	

Find even more online! Go to [ColeParmer.com](http://ColeParmer.com) to search more than 100,000 products.