


Thermo Scientific™ Nalgene™ Versi-Dry™ Absorbent Lab Soakers

Protect glassware and surfaces

- No more difficult clean-ups with quick absorbing material
- Skid resistant, polyethylene backing grips surface and retains liquids

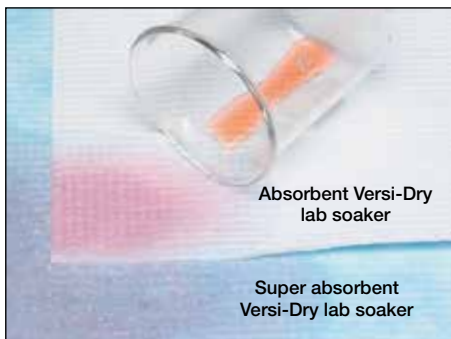

Absorbent Versi-Dry lab soaker

Super absorbent Versi-Dry lab soaker

Buy More...Save More!



20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases

| Sq ft/ pk | Size (W x L) | Catalog number | Qty/ pk | Price/pk |
|--|--------------------------------------|-----------------------------|------------|----------|
| Absorbent lab soakers, absorb 750 mL/m² | | | | |
| 1000 | 20" x 300 ft (50.8 cm x 91.4 m) roll | GH-06803-30 | 2 rolls | |
| 875 | 18" x 20" (45.7 x 50.8 cm) mat | GH-06803-32 | 350 mats | |
| Super absorbent lab soakers, absorb 1050 mL/m² | | | | |
| 417 | 20" x 250 ft (50.8 cm x 76.2 m) roll | GH-06803-40 | 1 roll | |
| 125 | 18" x 40" (45.7 x 101.6 cm) mat | GH-06803-42 | 25 mats | |
| 150 | 20" x 43" (50.8 x 109.2 cm) mat | GH-06803-44 | 25 mats | |

BYTAC® Surface Protectors Won't let corrosive materials through

- Protect surfaces from corrosion and absorption of toxic materials
- Pressure-sensitive backing—just peel backing and apply to surface
- Just wipe clean or wash down




FEP-coated BYTAC is ideal for use in kitchens and laboratories.

| Support material | Support material color | Thick-ness | Max temp. | Roll width | Roll length | Catalog number | Price/roll |
|------------------|------------------------|------------|---------------|----------------|---------------|-----------------------------|------------|
| Vinyl | White | 8 mm | 200°F (93°C) | 12½" (31.8 cm) | 15 ft (4.5 m) | GH-06804-20 | |
| | | | | 25" (63.5 cm) | | GH-06804-00 | |
| Aluminum | Silver | 2 mm | 360°F (182°C) | 12½" (31.8 cm) | | GH-06804-30 | |
| | | | | 25" (63.5 cm) | | GH-06804-10 | |

LABMAT™ Liners and Sheets Clean up spills easily

- Disposable liners absorb most liquids
- Easily cut to fit any area
- Won't leak or skid with polyethylene backing

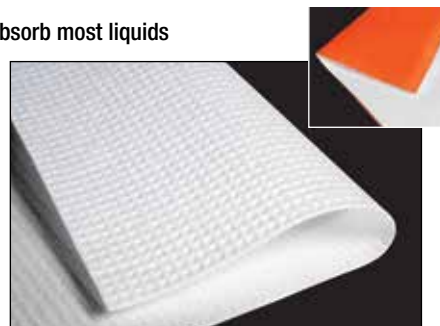

| Color | Size (W x L) | Catalog number | Qty | Price |
|--------|-------------------------------|-----------------------------|-----------------|-------|
| White | 20" x 50 ft (50.8 cm x 15 m) | GH-06805-01 | 1 roll | |
| Orange | 20" x 50 ft (50.8 cm x 15 m) | GH-06805-03 | 1 roll | |
| White | 20" x 24" (50.8 cm x 61.0 cm) | GH-06805-05 | 100 sheets/case | |

BenchGuard™ Absorbent Bench Protectors

No need for scissors

- Precut sheets for quicker placement
- Keep spills contained with absorbent upper surface and polycoated base
- Absorb twice as much with BenchGuard Extra



06806-00

06805-00

| Description | Absorbency | Size (W x L) | Catalog number | Pack | Price |
|------------------|-----------------------|-------------------------------|-----------------------------|------------|-------|
| BenchGuard | 400 mL/m ² | 19.3" x 164 ft (49 cm x 50 m) | GH-06805-00 | 1 roll | |
| | | 19.3" x 24" (49 cm x 61 cm) | GH-06806-00 | 100 sheets | |
| BenchGuard Extra | 800 mL/m ² | 19.3" x 164 ft (49 cm x 50 m) | GH-06805-10 | 1 roll | |
| | | 19.3" x 24" (49 cm x 61 cm) | GH-06806-10 | 50 sheets | |

Neotex® Liners, Neoprene-Coated Fiber Contour to your needs

- Cut to fit—easily contours to irregular surfaces
- Deadens sounds of items being placed or dropped
- Autoclavable



(Shown at actual size)

| Mesh opening | Material | Thickness | Max temp. | Roll size (W x L) | Catalog number | Price/roll |
|--------------|----------|-----------|---------------|------------------------------|-----------------------------|------------|
| ¼" (6 mm) | Black | 0.125" | 250°F (121°C) | 26" x 50 ft (66.0 cm x 15 m) | GH-09400-01 | |
| | Red | | | | GH-09400-02 | |
| | Green | | | | GH-09400-03 | |
| | Almond | | | | GH-09400-04 | |