


Advantec® Disposable 50-mm Sterile Petri Dishes, PS

No need to pre-sterilize

- Sterilized dishes are ready to use
- Use only what you need—come in convenient packs of 20
- Polystyrene dishes come with or without 47-mm absorbent cellulose pad that hold 1.8 to 2.0 mL of liquid media
- Ridges for easy stacking

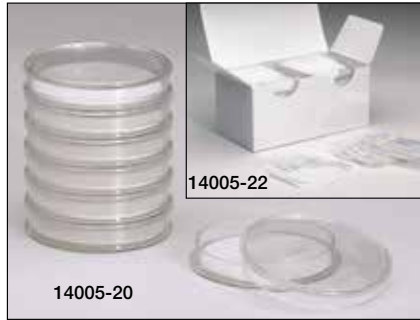

Description	Dia x H (mm)	Qty/cs	Catalog number	Price/cs
Petri dish with pad	50 x 11	100	GH-14005-20	
		500	GH-14005-28	
Petri dish without pad	50 x 11	100	GH-14005-24	
		500	GH-14005-26	

GH-14005-22 Presterilized absorbent pads. Box of 100 individual packages

Thermo Scientific™ Nunc™ Lab-Tek™ Sterile Petri Dishes, PS

Get better cultures

- Ideal for fungi, bacteria, and other microorganisms
- Sterilized by gamma irradiation



Dia x H (mm)	Vented	Stacking ring	Qty/cs	Catalog number	Price/cs
100 x 15	Yes	No	320	GH-14007-01	
60 x 20	Yes	Yes	400	GH-14007-03	
100 x 25	No	Yes	300	GH-14007-04	
140 x 20	Yes	No	80	GH-14007-05	
150 x 25	No	No	72	GH-14007-14	
100 x 15	Yes	No	500	GH-14007-10	

†Model 14007-10 is square in shape

Wait!

**There's More at
ColeParmer.com**

- ✓ Search **100,000+** products
 - ✓ Find full **product details**
- And much more!

Sterile Petri Dishes, PS

Stacks won't tip over—convenient stacking ridges for better stability

- Use what you need—packaged in bags of 20 dishes
- Save time—already sterilized by gamma irradiation



Buy More... Save More!

- 20% off on 120+
- 15% off on 30 to 119
- 10% off on 6 to 29 packs or cases



Dia x H (mm)	Qty/pk	Catalog number	Price/pk
60 x 15	500	GH-06139-01	
100 x 15	500	GH-06139-00	
150 x 20	100	GH-06139-02	

Thermo Scientific™ Nalgene™ Sterile Media Bottles, PETG

No pre-washing needed

- Radiation-sterilized and nonpyrogenic—no need to wash, depyrogenate, or autoclave
- PETG bottle with HDPE closures for long term storage and sterility



Capacity mL (oz)	Closure size	Qty/cs	Catalog number	Price/cs
30 (1)	20 mm	96	GH-06254-00	
60 (2)	24 mm	96	GH-06254-10	
125 (4)	38-430 mm	48	GH-06254-20	
250 (8)	38-430 mm	48	GH-06254-30	
500 (16)	38-430 mm	24	GH-06254-40	
1000 (32)	38-430 mm	24	GH-06254-50	
2000 (128)	53B mm	12	GH-06254-60	

Oxford® Bacti-Cinerator® IV

No more cross-contamination

- Safely and conveniently sterilize platinum loops and needles
- Don't waste time—sterilize in just 5 to 7 seconds
- Infrared heat has optimum sterilizing temperature of 1500°F
- Safe to use in anaerobic chambers



Description	Power(VAC,HZ)	Catalog number	Price
Bacti-Cinerator IV	120, 60	GH-01850-22	
	220, 50/60	GH-01850-24	

GH-01850-26 Replacement heater element for 01850-22

GH-01850-28 Replacement heater element for 01850-24