

### L/S® Variable-Speed Digital Drives

#### Versatile, worry-free operation

- Brushless, maintenance-free motor provides ±0.1% speed control accuracy with 6000:1 turndown ratio
- Bright graphical LCD offers easy programming, four operating modes, and seven languages
- Get more accurate dispensing with preprogrammed calibration
- Change based on your needs—drives accept all L/S pump heads for more pumping versatility
- Choose how you want to dispense: volume, copy cycles, or time
- Operate remotely via DB25 female connector

#### FEATURES

- ✓ Flow rates: 0.001 to 3400 mL/min
- ✓ Variable speed from 0.02 to 600 rpm
- ✓ Programmable, reversible motor accepts up to four pump heads
- ✓ Ensure dispensing accuracy with antidrip function
- ✓ Hands-free dispensing via time interval dispense cycles

Four operating modes for more functionality: continuous run, time dispense, copy dispense, and volume dispense



#### Flow Rates in mL/min (flow rates in parentheses can only be obtained with the High-Performance pump head—at ColeParmer.com)

rpm	Precision pump tubing						High-performance precision pump tubing			
	L/S 13	L/S 14	L/S 16	L/S 25	L/S 17	L/S 18	L/S 15	L/S 24	L/S 35	L/S 36
	Standard†, Easy-Load, Easy-Load II, Easy-Load 3						Multichannel‡, Standard, Easy-Load II, Easy-Load 3, High-Performance			
	Cartridge, Multichannel			Cartridge			Easy-Load			
0.1 to 600	0.006 to 36	0.021 to 130	0.08 to 480	0.17 to 1000	0.28 to 1700	0.38 to 2300	0.17 to 1000 (0.18 to 1100)	0.28 to 1700 (0.30 to 1800)	0.38 to 2300 (0.43 to 2600)	0.48 to 2900 (0.57 to 3400)
0.02 to 100	0.001 to 6	0.004 to 21	0.016 to 80	0.033 to 170	0.057 to 280	0.077 to 380	0.033 to 170 (0.036 to 183)	0.057 to 280 (0.057 to 300)	0.077 to 380 (0.086 to 433)	0.096 to 480 (0.113 to 566)

†The Standard pump head is not available for L/S® 25.

‡Multichannel head is not available for L/S 36. Multichannel and Cartridge heads are available for microbore tubing.




rpm	Speed control (resolution)	Pump heads accepted	Motor size	IP rating	Dimensions (L x W x H)	Power (50/60 Hz)		Catalog number	Price
						VAC	Amps		
0.1 to 600	±0.1% (0.1 rpm at 600 rpm; 0.01 rpm at 100 rpm)	2	1/10 hp (75 W)	IP33	10" x 8.5" x 8.5" (25.4 x 21.6 x 21.6 cm)	90 to 260	2.2 at 115 VAC, 1.1 at 230 VAC	<a href="#">GH-07522-20</a>	
0.02 to 100		4						<a href="#">GH-07522-30</a>	

#### Accessories

- [GH-07523-92](#) Foot switch, momentary start/stop; 6-ft (1.8-m) cable
- [GH-07523-94](#) DB25 male connector. Use to create your own cable
- [GH-07523-95](#) Cable assembly, DB25 male connector and 25 ft (7.9 m) cable with stripped wire ends for remote control

- [GH-07523-97](#) Handheld remote controller; route tubing through handle for dispensing into containers
- [GH-17050-01](#) NIST-traceable calibration with data for peristaltic pump drive

Choose a Complete System  
One catalog number includes all 3!

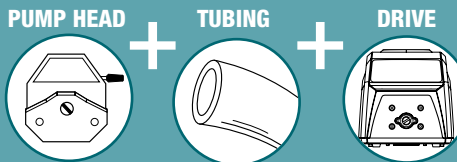

System	Flow range	What's included			Power	Catalog number	Price
		Pump head	Tubing	Drive			
	0.08 to 480 mL/min	Easy-Load® 3 77800-60	C-Flex® ULTRA L/S 16 tubing 06434-16 10 ft (3 m)	Digital drive 07522-20 0.1 to 600 rpm	90 to 260 VAC, 50/60 Hz	<a href="#">GH-77921-65</a>	
	0.28 to 1700 mL/min	Easy-Load II 77200-62	C-Flex ULTRA L/S 24 tubing 06434-24 10 ft (3 m)			<a href="#">GH-77921-75</a>	