


Economical Storage Boxes, PP

Won't deteriorate in moisture

- Use in temperatures down to -80°C (-112°F)
- Easily identify samples through translucent lids
- Autoclavable

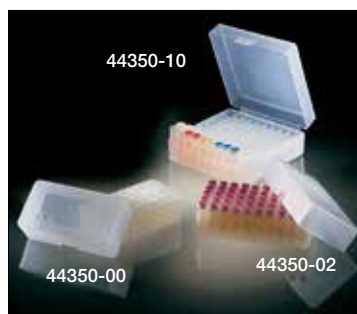

Tube size (mL)	Tubes held	Maximum tube length (mm)	Qty/pk	Catalog number	Price/pk
Boxes with unattached lid					
0.5	50	31	6	GH-44350-00	
1.5	50	43	6	GH-44350-02	
Box with hinged lid					
1.5	100	49	6	GH-44350-10	

Test Tube Support System, PP

One rack, virtually limitless versatility

- Rotate cubes to accommodate different size tubes
- Consists of four cubes and tray
- Autoclavable



Compatible tube sizes	Catalog number	Price
15- and 50-mL conical; 12 x 75 mm, 13 x 100 mm, 16 x 125 mm, and 17 x 100 mm culture; and 1.5- and 2.0-mL microcentrifuge	GH-06733-00	

Thermo Scientific™ Nalgene™ Unwire™ Test Tube Racks, Resmer®

Chip, scratch, and corrosion resistant


- Position in waterbaths or freezers with ease
- Autoclavable

Buy More... Save More!



20% off on 120+
15% off on 30 to 119
10% off on 6 to 29 packs or cases

Tube size (mm)	Tubes held (array)	Color	Qty/pk	Catalog number	Price/pk
13	72 (6 x 12)	White	1	GH-06737-50	
13	72 (6 x 12)	Orange	1	GH-06737-51	
13	72 (6 x 12)	Yellow	1	GH-06737-52	
13	72 (6 x 12)	Blue	1	GH-06737-53	
13	72 (6 x 12)	Green	1	GH-06737-54	
13	72 (6 x 12)	Red	1	GH-06737-55	
16	72 (6 x 12)	White	1	GH-06737-60	
16	72 (6 x 12)	Orange	1	GH-06737-61	
16	72 (6 x 12)	Yellow	1	GH-06737-62	
16	72 (6 x 12)	Blue	1	GH-06737-63	
16	72 (6 x 12)	Green	1	GH-06737-64	
16	72 (6 x 12)	Red	1	GH-06737-65	
20	40 (4 x 10)	White	1	GH-06737-70	
25	40 (4 x 10)	White	1	GH-06737-80	
30	24 (3 x 8)	White	1	GH-06737-90	

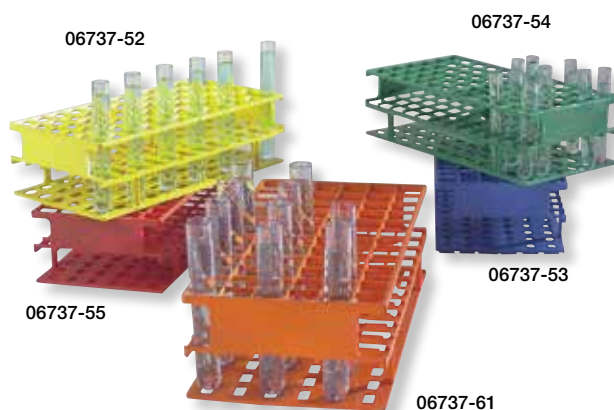

Scienceware® Switch-Grid™ Tube Racks

Get 25 racks in one!

- One rack provides up to 25 possible tube size combinations with quick changes
- Accommodates up to two different-sized tubes in the same rack
- Less expensive than purchasing multiple racks
- Chemical-resistant design provides easy cleaning
- Autoclavable

Tube size (mm)	No. of tubes held (array)	Catalog number	Price
10 to 13	84 (14 x 6)	GH-06736-12	
13 to 16	60 (12 x 5)	GH-06736-13	
16 to 20	40 (10 x 4)	GH-06736-14	
20 to 25	24 (8 x 3)	GH-06736-16	
25 to 30	12 (6 x 2)	GH-06736-17	



Accessories

- [GH-06736-18](#) Grid inserts for 10 to 13 mm tubes; orange. Set of 4
- [GH-06736-19](#) Grid inserts for 13 to 16 mm tubes; blue. Set of 4
- [GH-06736-22](#) Grid inserts for 16 to 20 mm tubes; green. Set of 4
- [GH-06736-23](#) Grid inserts for 20 to 25 mm tubes; fuchsia. Set of 4
- [GH-06736-24](#) Grid inserts for 25 to 30 mm tubes; yellow. Set of 4