


## H-B Instrument Enviro-Safe® Double-Safe™ Nonhazardous PFA-Coated Safety Glass Thermometers

No more glass or contamination if the thermometer breaks

- Filling and glass are contained within the PFA jacket, preventing leakage
- Enviro-Safe liquid within the thermometers is nontoxic, nonhazardous, and fully biodegradable
- Replace mercury thermometers with the same accuracy without any hazards
- Easily clean up spills with soap and water

Each thermometer features a black liquid and yellow back glass which creates a distinct contrast making this thermometer very easy to read. These thermometers also have ring top, antiroll fitting, individual serial numbers, and a statement of accuracy supplied by the manufacturer.

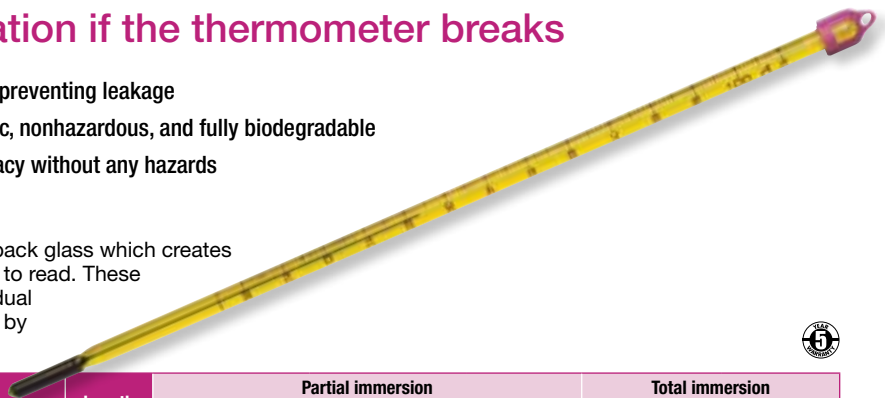

Temperature range	Scale divisions	Accuracy	Length	Partial immersion			Total immersion	
				Catalog number	Immersion depth	Price	Catalog number	Price
<b>Celsius-scale thermometers</b>								
-10 to 110°C	1°	±1°	200 mm	<a href="#">GH-08077-03</a>	50 mm		<a href="#">GH-08077-05</a>	
-10 to 150°C	1°	±1°; ±1.5° above 110°C	200 mm	<a href="#">GH-08077-06</a>	50 mm		<a href="#">GH-08077-07</a>	
-20 to 110°C	1°	±1°	300 mm	<a href="#">GH-08077-13</a>	76 mm		<a href="#">GH-08077-14</a>	
-20 to 150°C	1°	±1°; ±1.5° above 110°C	300 mm	<a href="#">GH-08077-15</a>	76 mm		<a href="#">GH-08077-16</a>	
-10 to 70°C	0.5°	0.05°	300 mm	<a href="#">GH-90300-01</a>	76 mm		—	—
-10 to 225°C	1°	1.5°, 2° above 110°C, 2.5° above 200°C	350 mm	—	—	—	<a href="#">GH-90300-07</a>	—
-10 to 260°C	1°	1.5°; ±2° above 110°C; 2.5° above 200°C	350 mm	<a href="#">GH-90300-03</a>	76 mm		—	—
<b>Fahrenheit-scale thermometers</b>								
20 to 230°F	2°	±2°	200 mm	<a href="#">GH-08077-08</a>	50 mm		<a href="#">GH-08077-09</a>	
20 to 300°F	2°	2°, 3° above 230°F	200 mm	<a href="#">GH-08077-11</a>	50 mm		<a href="#">GH-08077-12</a>	
0 to 230°F	2°	±2°	300 mm	<a href="#">GH-08077-17</a>	76 mm		<a href="#">GH-08077-18</a>	
0 to 300°F	2°	3°, 4° above 230°F	300 mm	<a href="#">GH-08077-19</a>	76 mm		<a href="#">GH-08077-26</a>	
20 to 500°F	2°	±2°; ±3° above 221°F; 4° above 392°F	350 mm	<a href="#">GH-90300-05</a>	76 mm		—	—

## H-B Instrument Easy-Read® Enviro-Safe® Certified Nonhazardous Glass Thermometers

Maximize your accuracy—individually calibrated

- Replace mercury thermometers with the same accuracy without any hazards
- 100% nontoxic, nonhazardous, biodegradable, and “green”—liquid easily cleans with soap and water
- NIST-traceable detailed, laminated Report of Calibration

Each thermometer features a black liquid and yellow back glass which creates a distinct contrast that is easy to read. Thermometers come complete with ring top anti-roll fitting, individual serial number and NIST-traceable calibration report supplied by the manufacturer.



Temperature range	Scale divisions	Accuracy	Length	Calibration points	Partial immersion			Total immersion	
					Catalog number	Immersion depth	Price	Catalog number	Price
<b>Celsius-scale thermometers</b>									
-10 to 70°C	0.5°	0.5°	300 mm	0, 37, 56°C	<a href="#">GH-08008-47</a>	76 mm		—	
-20 to 110°C	1°	1°	300 mm	0, 50, 100°C	<a href="#">GH-08008-48</a>	76 mm		<a href="#">GH-08008-49</a>	
-20 to 110°C	1°	1°	300 mm	0, 37, 56°C	<a href="#">GH-08008-52</a>	76 mm		<a href="#">GH-08008-53</a>	
-20 to 110°C	1°	1°	300 mm	0, 4, 20, 37, 44.5, 103°C	<a href="#">GH-90300-31</a>	76 mm		—	
-20 to 150°C	1°	1°	300 mm	0, 60, 120°C	<a href="#">GH-08008-50</a>	76 mm		<a href="#">GH-08008-51</a>	
-10 to 225°C	1°	1°	350 mm	1, 100, 200°C	—	—		<a href="#">GH-08008-54</a>	

### Thermometer Holder with Clip

- Hands-free support—clips to vessel side
- Accommodates thermometers from 4 to 14 mm dia



Description	Catalog number	Price
Thermometer holder with clip	<a href="#">GH-08120-90</a>	

### Antiroll Fittings

- Keep thermometer in place—slide onto standard size thermometer to prevent rolling



Style	Catalog number	Qty/pk	Price
Ring top	<a href="#">GH-08007-98</a>	25	
Triangular	<a href="#">GH-08007-99</a>	25	