

### Technician's Tool Kits

Our most elaborate assortment for your repair needs

These tool kits feature 53 individual hand tools, 31 interchangeable screwdriver/nutdriver blades and handles, and two specialized screwdriver/nutdriver kits.

**Contains:**

- 3 handles: regular, regular ratchet, and tee ratchet
- 1 torque amplifier handle
- 2 extensions
- 1 reamer
- 4 slotted screw blades
- 3 Phillips® screw blades
- 9 Bristol six-flute multiple spine blades
- 9 Allen® hex socket blades
- 1 straight nose seizer
- 1 adjustable wrench
- 1 midget slip-joint pliers
- 1 long nose pliers
- 1 utility pliers
- 2 diagonal pliers
- 1 needle nose pliers
- 1 chain nose pliers
- 1 electronic snips
- 1 wire cutter/stripper
- 1 electrician's knife
- 1 mini driver
- 5 offset ratchet screwdrivers
- 1 combo screwdriver/nutdriver tool
- 1 dual reversible screwdriver blade
- 12 slotted screwdrivers
- 4 Phillips screwdrivers
- 2 hex socket screwdrivers
- 8 hollow shaft nutdrivers
- 2 magnetic nutdrivers
- 10 midget nutdrivers
- Carrying case



09900-70




09900-82

Description	Catalog number	Price
Tool kit in a polyethylene case	<a href="#">GH-09900-70</a>	
Tool kit in a polyethylene case with wheels	<a href="#">GH-09900-82</a>	

### Fowler® Precertified Rules

Easy-to-read graduations on a nonglare satin chrome finish

Each Fowler precertified rule for ISO/QS9000 requirements includes a certificate of calibration.

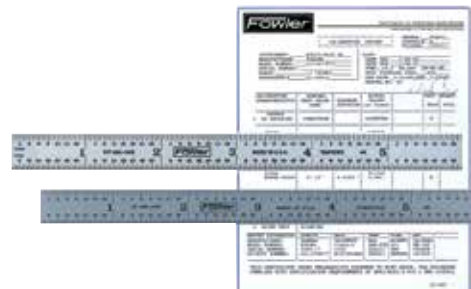

Model	Style	Size	Graduation	Catalog number	Price
52-264-006	Flexible	6"/150 mm	1/32", 1/64", 1 mm, 0.5 m	<a href="#">GH-09919-06</a>	
52-264-012	Flexible	12"/300 mm		<a href="#">GH-09919-16</a>	
52-265-006	Rigid	6"/150 mm		<a href="#">GH-97604-57</a>	
52-265-012	Rigid	12"/300 mm		<a href="#">GH-97604-58</a>	
52-265-024	Rigid	24"/600 mm		<a href="#">GH-97604-59</a>	
52-411-006	Flexible	6"	1/8", 1/16", 1/32", 1/64"	<a href="#">GH-09919-00</a>	
52-411-012	Flexible	12"		<a href="#">GH-09919-11</a>	
52-411-018	Flexible	18"		<a href="#">GH-97604-30</a>	
52-411-024	Flexible	24"		<a href="#">GH-09919-21</a>	
52-413-006	Rigid	6"		<a href="#">GH-09919-04</a>	
52-413-012	Rigid	12"		<a href="#">GH-09919-14</a>	
52-413-018	Rigid	18"		<a href="#">GH-97604-34</a>	
52-413-024	Rigid	24"		<a href="#">GH-09919-25</a>	
52-511-006	Flexible	6"		<a href="#">GH-09919-02</a>	
52-511-012	Flexible	12"		1/32", 1/64", 1/10", 1/100"	<a href="#">GH-09919-12</a>
52-511-018	Flexible	18"		<a href="#">GH-97604-31</a>	
52-511-024	Flexible	24"		<a href="#">GH-09919-23</a>	

### Hardman® Epoxy and Urethane Adhesives

Complete selection of epoxies for all your maintenance needs

– Single-use adhesives are perfect for quick repair jobs

Epoxies and urethanes come in handy 3.5-gram, two-component packets and mixing sticks. Choose from individual packets or two kit options providing an assortment of 100 epoxies and urethanes. Kits are available as a tool box with a removable tray or a satchel case divided into 15 compartments.

**What's included:** packets include 10 epoxy or urethane packs and mixing sticks. Kits (sold below in table) include 100 mixing sticks;

30 packets of quick-set epoxy (08778-02); 10 packets each of quick-set, non-sag epoxy (08778-04) and general-purpose epoxy (08778-06); five packets each of high peel-strength epoxy (08778-08), machinable epoxy (08778-10), wet-surface epoxy (08778-12), general-purpose urethane (08778-20), high peel-strength urethane (08778-22), high shear-strength urethane (08778-24), regular setting epoxy, water clear epoxy, fast setting silicone, and hand cleaner.



Description	Applications	Temperature range	Set time	Curing time	Qty/pk	Catalog number	Price/pk*
Epoxy, quick -set	Wood, metal, glass, stone, concrete, and leather	-20 to 180°F	3 to 5 min	24 hr	10	<a href="#">GH-08778-02</a>	
Epoxy, quick-set, non-sagging	Wood, metal, glass, ceramic, leather, and rubber; won't run or drip on vertical or overhead applications	-20 to 180°F	3 to 5 min	24 hr	10	<a href="#">GH-08778-04</a>	
Epoxy, general-purpose	Wood, metal, plastic, rubber, fiberglass, cloth and ceramic	-30 to 200°F	3 hr	7 day	10	<a href="#">GH-08778-06</a>	
Epoxy, high peel-strength	Wood, metal, masonry, rubber, polystyrene, ABS and nylon; tough, vibration-resistant	-40 to 250°F	4 hr	7 day	10	<a href="#">GH-08778-08</a>	
Epoxy, quick-set, machinable	Wood, metals, and hard plastics; drill, tap, and sand	-20 to 300°F	25 min	14 day	10	<a href="#">GH-08778-10</a>	
Epoxy, wet-surface patching	Wood, glass, stone, fiberglass, concrete, and metal; wet and underwater use	-20 to 225°F	25 min	7 day	10	<a href="#">GH-08778-12</a>	
Urethane, general-purpose	Most metals, glass, plastics, rubber and leather; rollers and rubberized fabrics	-40 to 150°F	8 min	7 day	10	<a href="#">GH-08778-20</a>	
Urethane, high peel-strength	Plastics, rubber, leather, and china; automotive repairs	-40 to 175°F	4 to 8 min	24 hr	10	<a href="#">GH-08778-22</a>	

\*Save 10% On 10 or more packs

[GH-08778-30 Tool box kit](#), includes 100 mixing sticks and assortment of 100 epoxies and urethanes (see above for assortment)

[GH-08778-32 Satchel case kit](#), includes 100 mixing sticks and assortment of 100 epoxies and urethanes (see above for assortment)