
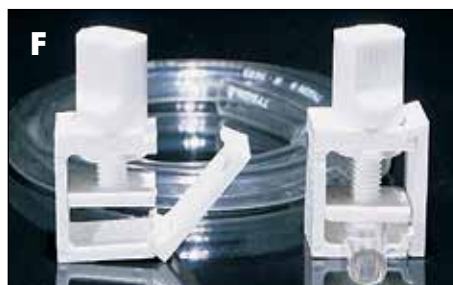
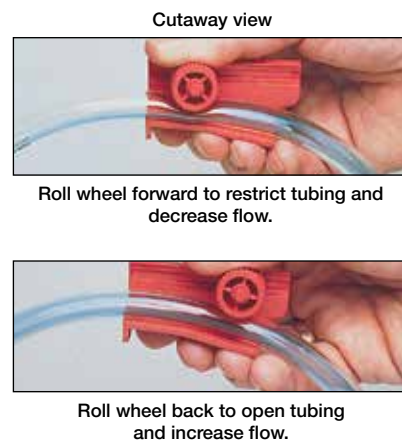


Tubing Accessories

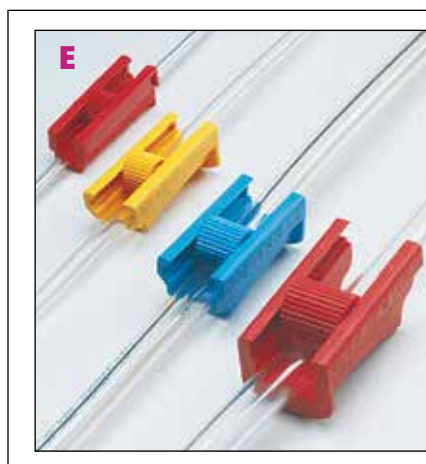

A. Spring Tubing Clamps

Acetal copolymer and stainless steel clamps provide on/off flow control for flexible tubing. Chemically resistant.

Max tubing OD	Catalog number	Price/pk of 3
5/16" (8 mm)	GH-06834-10	
1/2" (12 mm)	GH-06834-20	

B. Steel Tubing Clamps

Remove zinc-plated steel clamps without disconnecting or damaging tubing. Strong enough for heavy vacuum lines and will not slip.

Max tubing OD	Catalog number	Price/ea
3/8" (10 mm)	GH-06404-10	
9/16" (15 mm)	GH-06404-20	
3/4" (20 mm)	GH-06404-30	

C. In-Line Flow Indicators

Indicators give visual confirmation of flow through a clear polystyrene housing. Use with noncorrosive liquids and gases. Connect tubing to indicators via hose barb connections; model 06297-05 has straight ends. Pressure rated to 10 psig.

Flow range (L/min)	Tubing ID	Indicator type (PP)	Max fluid temperature	Catalog number	Price/pk***
0.2 to 6.5	1/4" to 3/8"	Ball	125°F (50°C)	GH-06297-00	
0.5 to 10.0	1/4"	Paddle	150°F (65°C)	GH-06297-05	
0.5 to 10.0	3/16" to 1/4"	Paddle	150°F (65°C)	GH-06297-06	
0.5 to 10.0	1/4" to 7/16"	Paddle	150°F (65°C)	GH-06297-07	

***Discounts: Save 10% on 12–59 pks, 15% on 60–239 pks, and 20% on 240+ pks.

D. Poly-Cone™ Taper Adapter

Polypropylene cone is 27-cm (10⁵/₈" long; cut to fit your needs. Tapers from 30- to 3-mm ID (35- to 8-mm OD). Withstands temperatures to 250°F (121°C).

[GH-06432-00](#) Poly-Cone taper adapter

E. Keck® Ramp Clamp® Tubing Clamps

– One-handed flow control

Keck Ramp Clamp tubing clamps feature a unique wheel-in-groove design that permits one-handed flow control. Simply remove wheel to insert tubing, then roll wheel back into clamp to adjust flow rate.

Keck clamps are color-coded for easy size identification. All four sizes accept tubing with a maximum wall thickness of 3/32" (2.4 mm). Clamps are made of polybutylene terephthalate; safe to 392°F (200°C).

Max tubing OD	Catalog number	Price/pk of 12
3/16" (4.5 mm)	GH-06835-05	
1/4" (4.6 mm)	GH-06835-03	
3/8" (10 mm)	GH-06835-07	
9/16" (14 mm)	GH-06835-10	

[GH-06841-80](#) Tubing clamp assortment kit. Contains eight each of 06835-05, -03, -07, and -10 clamps (32 pieces total)

F. Screw Clamp

Clamp is made of Delrin® acetal and is resistant to weak acids, bases, and organic solvents. Control flow in flexible tubing up to 1/2" (13 mm) OD. Replaces stopcocks in many applications. Install without disconnecting tubing. Autoclavable.

[GH-06833-10](#) Screw clamp. Pack of 3

G. Ratchet Tubing Clamps

Durable Celcon® plastic clamp is autoclavable; won't rust, corrode, or distort. Twelve-position ratchet control adjusts from full flow to complete closure. Mini-clamp is suitable for up to 1/8" OD tubing. Standard clamp accepts flexible tubing to 1/2" OD.

Description	Catalog number	Qty/pk	Price
Mini tubing clamp	GH-06833-01	25	
Tubing clamp	GH-06833-00	25	