

Cleanroom Paper, Notebooks, and Notepads

Don't contaminate work space

Cleanroom Paper is made without organic fillers to substantially reduce the risk of particle generation and contamination. Paper has excellent strength and heat resistance for use in copy machines and laser printers. Sheets measure 8½" x 11". Select from 22 or 18 weight paper.

Compliance: ISO Class 5



Description	Weight	Sheets/cs	Catalog number	Price/cs
Blue	22	2500	GY-33678-00	
Blue	18		GY-33678-06	
White	22		GY-33678-01	
Yellow	22		GY-33678-03	
Green	22		GY-33678-04	

Cleanroom Notebooks are an economical choice for note taking and data recording in your cleanroom. Notebooks feature a high-density polyethylene cover, plastic spirals, and durable cleanroom paper. Pages are printed with low sodium ink to reduce contamination.

Compliance: ISO Class 4

Size	Description	Qty/bx	Catalog number	Price/bx
8½" x 11" (21.6 x 27.9 cm)	College ruled	10	GY-33678-21	
5½" x 8½" (14 x 21.6 cm)	College ruled	10	GY-33678-23	

Cleanroom Self-Adhesive Notepads are ideal for adding notes to documents and equipment in your cleanroom without the risk of contamination. They feature a low-residue, temporary adhesive strip for easy attachment and removal. Packaged 72 sheets/pad.

Compliance: ISO Class 4


Size	Description	Qty/bx	Catalog number	Price/bx
3" x 4" (7.6 x 10.2 cm)	Self-adhesive	10	GY-33678-30	

Stainless Steel Work Tables

No assembly required

- Resist rigors of everyday use—made entirely of 16-gauge Type 304 stainless steel
- Working height of 36", one-inch adjustable bullet feet are included
- Handles up to 400 lb

Approval: NSF

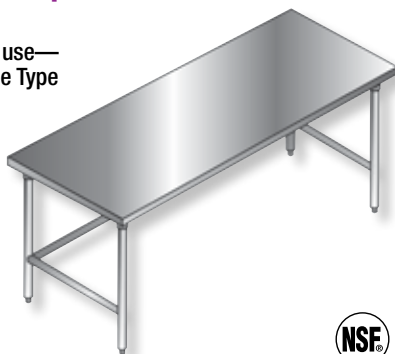

Shelf size	Shpg wt	Catalog number	Price
30"L x 24"W (76.2 x 61 cm)	80 lb (37.5 kg)	GY-86519-00	
48"L x 24"W (121.9 x 61 cm)	95 lb (43 kg)	GY-86519-02	
72"L x 24"W (182.9 x 61 cm)	110 lb (50 kg)	GY-86519-04	
96"L x 24"W (243.8 x 61 cm)	150 lb (68 kg)	GY-86519-06	

Stainless Steel Work Tables with Rear Splash

Rugged, durable work surface

- Constructed from 16-gauge Type 304 stainless steel
- Includes a 5" rear splash and adjustable bottom shelf
- Working height is 35½", one-inch adjustable bullet feet are included
- Capacity is 900 lb.



Size	Shpg wt	Catalog number	Price
48"L x 30"W (121.9 x 76.2 cm)	92 lb (41.8 kg)	GY-47620-80	
60"L x 30"W (152.4 x 76.2 cm)	113 lb (51.3 kg)	GY-47620-82	
72"L x 30"W (182.9 x 76.2 cm)	129 lb (58.6 kg)	GY-47620-84	
96"L x 30"W (243.8 x 76.2 cm)	164 lb (74.4 kg)	GY-47620-86	

Cleanroom Stools

Stores under counter when not in use

- Easy pneumatic adjustments to accommodate multiple user's needs
- For mobility, order optional casters separately

Vinyl Stools feature dependable vinyl over soft foam padding.

ESD (Electrostatic Discharge)

Vinyl Stools also include a brass drag chain and ESD mushroom glides.

Compliance: ISO Class 5



86520-05 with optional casters

Seat height	Base type	Catalog number	Price	Optional casters	
				Cat. no.	Price/pk of 5
Vinyl stools, foot ring diameter 18" (46 cm)					
16½" to 21½" (42 to 55 cm)	Aluminum	GY-86520-01		GY-86309-96	
25" to 30" (64 to 76 cm)	Chrome tubular steel	GY-86520-02		GY-86309-90	
20" to 27" (51 to 69 cm)	Aluminum	GY-86520-03		GY-86309-96	
24" to 34" (61 to 86 cm)	Aluminum	GY-86520-05		GY-86309-96	
ESD vinyl stools, foot ring diameter 18" (46 cm)					
16½" to 21½" (42 to 55 cm)	Aluminum	GY-86520-11		GY-86309-93	
25" to 30" (64 to 76 cm)	Chrome tubular steel	GY-86520-12		GY-86309-92	
20" to 27" (51 to 69 cm)	Aluminum	GY-86520-13		GY-86309-93	
24" to 34" (61 to 86 cm)	Aluminum	GY-86520-15		GY-86309-93	