


Barbed Fittings (continued)

Barbed fittings are designed for quick and easy assembly without tools. Combine these simple, economical fittings with our flexible tubing for use in your low-pressure applications (generally less than 30 psi). Order tubing on pages 988–1017.

For material descriptions, refer to page 302.

T connectors

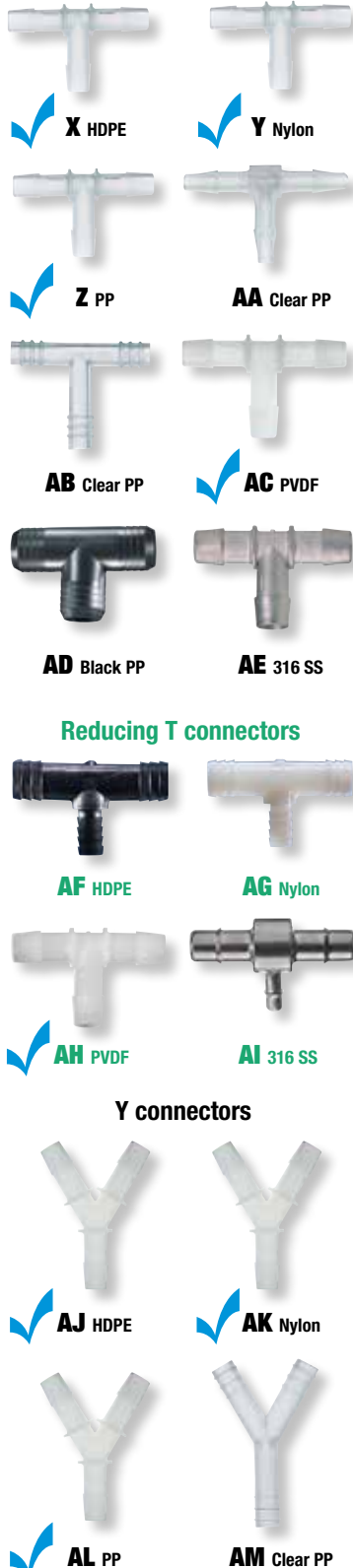

Tubing ID	Material	Key	Catalog number	Qty/ pk	Price/ pk
T connectors					
1/16"	Nylon	Y	GY-31500-30	25	
1/16"	HDPE	X	GY-30624-27	10	
1/16"	Nylon	Y	GY-30624-29	10	
1/16"	PP	Z	GY-40624-30	10	
1/16"	Clear PP	AA	GY-06365-77	25	
1/16"	PVDF	AC	GY-30703-70	10	
3/32"	HDPE	X	GY-30623-56	10	
3/32"	Nylon	Y	GY-30624-26	10	
3/32"	PP	Z	GY-40623-57	10	
3/32"	PP	Z	GY-40624-28	25	
3/32"	PVDF	AC	GY-30703-71	10	
1/8"	HDPE	X	GY-30623-64	10	
1/8"	Nylon	Y	GY-30623-65	10	
1/8"	PP	Z	GY-40623-66	25	
1/8"	PVDF	AC	GY-30703-72	10	
1/8"	316 SS	AE	GY-30620-25	1	
4 mm	Clear PP	AB	GY-06294-10	20	
3/16"	HDPE	X	GY-30623-67	10	
3/16"	Nylon	Y	GY-30623-69	10	
3/16"	PP	Z	GY-40623-70	25	
3/16"	PVDF	AC	GY-30624-31	10	
3/16"	316 SS	AE	GY-30620-26	1	
6 mm	Clear PP	AB	GY-06294-20	20	
1/4"	HDPE	X	GY-30623-71	10	
1/4"	Nylon	Y	GY-30623-72	10	
1/4"	PP	Z	GY-40610-30	10	
1/4"	PVDF	AC	GY-30703-75	10	
1/4"	316 SS	AE	GY-30620-27	1	
5/16"	HDPE	X	GY-30623-73	10	
5/16"	Nylon	Y	GY-30623-75	10	
5/16"	PP	Z	GY-40623-76	10	
5/16"	PVDF	AC	GY-30623-74	10	
5/16"	316 SS	AE	GY-30620-28	1	
8 mm	Clear PP	AB	GY-06294-30	20	
3/8"	HDPE	X	GY-30623-77	10	
3/8"	Nylon	Y	GY-30623-78	10	
3/8"	PP	Z	GY-40610-31	10	
3/8"	PVDF	AC	GY-30703-77	10	
3/8"	316 SS	AE	GY-30620-29	1	
10 mm	Clear PP	AB	GY-06294-40	20	
1/2"	HDPE	X	GY-30623-79	10	
1/2"	Nylon	Y	GY-30623-80	10	
1/2"	PP	Z	GY-40610-32	10	
1/2"	PVDF	AC	GY-30703-78	10	
1/2"	316 SS	AE	GY-30620-30	1	
12 mm	Clear PP	AB	GY-06294-50	20	
5/8"	HDPE	X	GY-30623-58	10	
5/8"	Nylon	Y	GY-30623-59	10	
5/8"	PP	Z	GY-40610-33	10	
5/8"	PVDF	AC	GY-30703-79	10	
5/8"	316 SS	AE	GY-30620-31	1	
14 mm	Clear PP	AB	GY-06294-60	10	
3/4"	HDPE	X	GY-30623-60	10	
3/4"	Nylon	Y	GY-30623-61	10	
3/4"	PP	Z	GY-40610-34	5	
3/4"	PVDF	AC	GY-30703-80	5	
3/4"	316 SS	AE	GY-30620-32	1	
16 mm	Clear PP	AB	GY-06294-70	10	
1"	HDPE	X	GY-30623-62	10	
1"	Nylon	Y	GY-30623-63	10	
1"	PP	Z	GY-40610-35	5	
1"	PVDF	AC	GY-30703-81	5	
1 1/4"	Nylon	Y	GY-31408-08	5	
1 1/4"	Black PP	AD	GY-31407-08	5	
1 1/2"	Nylon	Y	GY-31408-09	5	
1 1/2"	Black PP	AD	GY-31407-05	5	

Tubing ID	Material	Key	Catalog number	Qty/ pk	Price/ pk
Reducing T connectors (straight x branch)					
1/16" x 1/8"	316 SS	AI	GY-31208-41	1	
1/8" x 1/16"	316 SS	AI	GY-31208-42	1	
3/16" x 1/8"	316 SS	AI	GY-31208-44	1	
1/4" x 1/8"	316 SS	AI	GY-31208-45	1	
1/4" x 3/8"	316 SS	AI	GY-31208-46	1	
3/8" x 1/8"	316 SS	AI	GY-31208-47	1	
3/8" x 3/16"	HDPE	AF	GY-31702-47	10	
3/8" x 3/16"	Nylon	AG	GY-31702-45	10	
3/8" x 1/4"	Nylon	AG	GY-31702-57	10	
3/8" x 1/4"	316 SS	AI	GY-31208-48	1	
3/8" x 5/16"	316 SS	AI	GY-30620-33	1	
1/2" x 1/4"	Nylon	AG	GY-31702-61	10	
1/2" x 3/8"	HDPE	AF	GY-30401-56	10	
3/4" x 3/8"	PVDF	AH	GY-30703-96	10	
3/4" x 1/2"	HDPE	AF	GY-30401-59	10	
5/8" x 3/8"	HDPE	AF	GY-30401-63	10	
5/8" x 3/8"	PVDF	AH	GY-30703-95	10	
Y connectors					
1/16"	HDPE	AJ	GY-30726-01	10	
1/16"	Nylon	AK	GY-30726-21	10	
1/16"	PP	AL	GY-40726-41	10	
1/16"	PVDF	AO	GY-30703-90	10	
1/16"	316 SS	AP	GY-31209-55	1	
3/32"	HDPE	AJ	GY-30726-02	10	
3/32"	Nylon	AK	GY-30726-22	10	
3/32"	PP	AL	GY-40726-42	10	
3/32"	PVDF	AO	GY-30703-91	10	
1/8"	HDPE	AJ	GY-30726-03	10	
1/8"	Nylon	AK	GY-30726-23	10	
1/8"	PP	AL	GY-40726-43	10	
1/8"	PVDF	AO	GY-30703-92	10	
1/8"	316 SS	AP	GY-30620-21	1	
4 mm	Clear PP	AM	GY-06295-10	20	
4–6 mm	White PP	AN	GY-06296-10	20	
3/16"	HDPE	AJ	GY-30726-04	10	
3/16"	Nylon	AK	GY-30726-24	10	
3/16"	PP	AL	GY-40726-44	10	
3/16"	PVDF	AO	GY-30726-64	10	
3/16"	316 SS	AP	GY-30620-22	1	
6 mm	Clear PP	AM	GY-06295-20	20	
1/4"	HDPE	AJ	GY-30726-05	10	
1/4"	Nylon	AK	GY-30726-25	10	
1/4"	PP	AL	GY-40726-45	10	
1/4"	PVDF	AO	GY-30726-65	10	
6–8 mm	White PP	AN	GY-06296-20	20	
5/16"	316 SS	AP	GY-30620-23	1	
8 mm	Clear PP	AM	GY-06295-30	20	
8–10 mm	White PP	AN	GY-06296-00	20	
3/8"	HDPE	AJ	GY-30726-06	10	
3/8"	Nylon	AK	GY-30726-26	10	
3/8"	PP	AL	GY-40726-46	10	
3/8"	PVDF	AO	GY-30703-93	10	
3/8"	316 SS	AP	GY-30620-24	10	
10 mm	Clear PP	AM	GY-06295-40	20	
10–12 mm	White PP	AN	GY-06296-40	20	
12 mm	Clear PP	AM	GY-06295-50	20	
12–14 mm	White PP	AN	GY-06296-50	20	
1/2"	HDPE	AJ	GY-30726-07	10	
1/2"	Nylon	AK	GY-30726-27	10	
1/2"	PP	AL	GY-40726-47	10	
1/2"	PVDF	AO	GY-30703-94	10	