

### Lab Notebooks

#### Keep accurate records for easy recall

Laboratory notebooks feature numbered pages printed with either a green grid or green horizontal lines; additional pages include issuance page, instructions for keeping research records, and table of contents. Numbered pages have spaces for signatures and dates.

Choose either Polypaper or conventional paper. Uncoated Polypaper is highly resistant to moisture, chemicals, tearing, and aging; works best with ballpoint pen or felt-tip marker.



Format	Page size	No. of pages†	Cover color	Catalog number	Qty/pk	Price/pk
<b>Notebook with uncoated Polypaper, case bound in a hard waterproof cover</b>						
1/4-inch grid	9 1/4" x 11 1/4" (235 x 286 mm)	100	Black	<a href="#">GY-06551-00</a>	1	
<b>Notebook with conventional paper, case bound in a hard waterproof cover</b>						
1/4-inch grid	8 1/2" x 11" (216 x 279 mm)	100	Green	<a href="#">GY-06553-00</a>	1	
3 lines/inch	8 1/2" x 11" (216 x 279 mm)	100	Burgundy	<a href="#">GY-06556-00</a>	1	
5-mm grid	A4 (210 x 297 mm)	100	Green	<a href="#">GY-06553-10</a>	1	
<b>Notebook with conventional paper, permanently bound in a lightweight spill-resistant cover</b>						
1/4-inch grid	8 1/2" x 11" (216 x 279 mm)	184	Burgundy	<a href="#">GY-06553-05</a>	1	

†Quantity of numbered pages only.

### All-Weather Writing Paper

#### Write in all weather conditions

- Repels water so you can still take notes



#### Bound Books

- Durable, polydura covers with 156 numbered, 4 3/4" x 7 1/2" pages
- Meets US EPA guidelines

Description	Catalog number	Price
Environmental	<a href="#">GY-06570-00</a>	
Horizontal line	<a href="#">GY-06570-04</a>	

### Maxi-Spiral Notebooks


- Sturdy, polydura cover with spiral binding
- Contain 42 sheets of 8 1/2" x 11" of paper



Description	Catalog number	Price
Field pattern	<a href="#">GY-06570-30</a>	
Horizontal line	<a href="#">GY-06570-32</a>	

### Copier Paper

- Create your own charts, maps, or worksheets on all-weather paper
- Not for use with ink jet printers

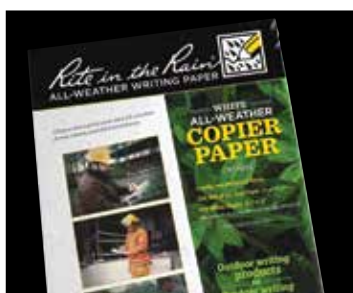

Description	Catalog number	Qty/pk	Price
White, 8 1/2" x 11" (216 x 279 mm)	<a href="#">GY-06570-24</a>	200	

### Cole-Parmer® Lab Markers

#### Won't bleed

- Write on cold, wet surfaces
- Permanent on plastic; washes off glass, metal, and porcelain




**Cole-Parmer®**

Color	Catalog number	Qty/pk	Price/pk
Black	<a href="#">GY-09964-00</a>	10	
Blue	<a href="#">GY-09964-10</a>	10	
Green	<a href="#">GY-09964-15</a>	10	
Red	<a href="#">GY-09964-20</a>	10	

### Permanent Paint Markers

#### Will not dry out

- Unique tip design eliminates drying out
- Writes on any surface

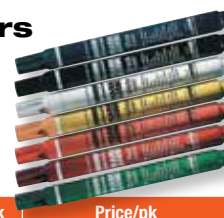

Color	Catalog number	Qty/pk	Price/pk
Blue	<a href="#">GY-09964-60</a>	12	
Black	<a href="#">GY-09964-61</a>		
White	<a href="#">GY-09964-62</a>		
Yellow	<a href="#">GY-09964-63</a>	12	
Orange	<a href="#">GY-09964-64</a>		
Red	<a href="#">GY-09964-65</a>		
Green	<a href="#">GY-09964-66</a>		

### Industrial Markers

#### Resists most chemicals, steam, and heat

- Permanent black ink
- Stands heat up to 500°F (260°C)



Tip	Catalog number	Qty/pk	Price/pk
Fine	<a href="#">GY-09969-00</a>	12	
Extra fine	<a href="#">GY-09969-10</a>		