

Brand 3170 and 3175 Trays

Easy to carry handles

- Steam sterilize with 3170 trays
- 3175 models are autoclavable
- Do not use over direct heat



Type	Capacity oz (L)	Dimensions	Cat. no.	Qty/pk	Price/pk
Drying (3175)	68 (2)	10 ⁷ / ₈ " x 6 ⁷ / ₈ " x 1 ¹ / ₂ " (27.7 x 17.6 x 3.8 cm)	GY-34588-20	4	
Drying (3175)	68 (2)	7 ¹ / ₈ " x 7 ¹ / ₈ " x 2" (18.1 x 18.1 x 5.1 cm)	GY-34588-22	4	
Drying (3175)	157 (4.5)	15" x 10" x 2" (38.1 x 25.4 x 5.1 cm)	GY-34588-26	4	
Sterilizing (3170)	270 (8)	18" x 12" x 2 ¹ / ₂ " (45.7 x 30.5 x 6.4 cm)	GY-34588-30	1	

Fiberglass Trays

Move samples easily

- Withstand temperatures from 0 to 180°F (-17 to 83°C)
- Autoclavable to 500°F (204°C) for short intervals



Color	Inside dimensions (L x W x H)	Catalog number	Qty/pk	Price/pk
White	13" x 10" x 3/4" (33 x 25.4 x 1.9 cm)	GY-06715-60	1	
	16" x 12" x 3/4" (40.6 x 30.5 x 1.9 cm)	GY-06715-62		
	18" x 14" x 3/4" (45.7 x 35.6 x 1.9 cm)	GY-06715-64		
Red	15" x 20" x 3/4" (38.1 x 50.8 x 1.9 cm)	GY-06715-66	1	
	13" x 10" x 3/4" (33 x 25.4 x 1.9 cm)	GY-06714-12		
	16" x 12" x 3/4" (40.6 x 30.5 x 1.9 cm)	GY-06714-14		
	18" x 14" x 3/4" (45.7 x 35.6 x 1.9 cm)	GY-06714-18		
	15" x 20" x 3/4" (38.1 x 50.8 x 1.9 cm)	GY-06714-16		

Rectangular Trays, High-Alumina

Eliminate contamination

- Highly resistant to chemicals
- Use for high-temperature and high-purity applications
- Autoclavable




Capacity (mL)	Dimensions (L x W x H)	Catalog number	Qty/cs	Price/cs
5	1 ¹ / ₂ " x 1 ¹ / ₄ " x 1/4" (3.8 x 3.2 x 0.6 cm)	GY-17826-00	1	
13	2 ³ / ₈ " x 1 ¹ / ₂ " x 1/4" (6 x 3.8 x 0.6 cm)	GY-17826-02		
32	3" x 2" x 1/2" (7.5 x 5 x 1.2 cm)	GY-17826-04		
64	4" x 1 ³ / ₄ " x 3/4" (10.2 x 4.5 x 1.9 cm)	GY-17826-06	1	
130	6" x 2 ¹ / ₂ " x 3/4" (15.2 x 6.5 x 1.9 cm)	GY-17826-08		
340	7 ¹ / ₈ " x 3 ¹ / ₂ " x 1" (20 x 9 x 2.5 cm)	GY-17826-10		
750	7 ⁵ / ₈ " x 5 ¹ / ₂ " x 1 ³ / ₄ " (19.4 x 14 x 4.4 cm)	GY-17826-12		

Chemical-Resistant Trays and Pans

Resist mild acids, alkalis, and reagents

- Withstand temperatures from -40 to 250°F (-40 to 121°C)
- Contain spills with straight edge pans

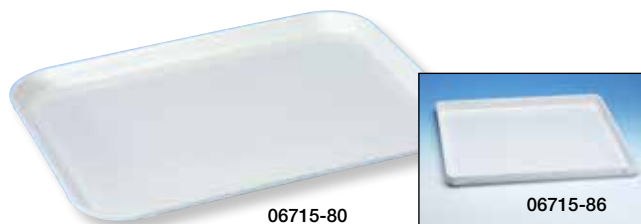

Outside dimensions (L x W x H)	Cat. no.	Qty/pk	Price/pk
Chemical-resistant trays			
13 ³ / ₄ " x 10 ⁵ / ₈ " x 1" (33.7 x 26.9 x 2.5 cm)	GY-06715-80	1	
18" x 14" x 1" (45.7 x 35.6 x 2.5 cm)	GY-06715-82	1	
20 ⁵ / ₈ " x 15 ¹ / ₈ " x 1" (52 x 38.3 x 2.5 cm)	GY-06715-84	1	
Chemical-resistant pans			
25 ¹ / ₄ " x 19 ¹ / ₄ " x 1 ¹ / ₈ " (64.1 x 48.9 x 2.7 cm)	GY-06715-86	1	
19 ¹ / ₂ " x 19 ¹ / ₂ " x 1 ¹ / ₄ " (49.5 x 49.5 x 3.2 cm)	GY-06715-88	1	
31" x 25" x 2 ³ / ₄ " (78.7 x 63.5 x 7 cm)	GY-06715-90	1	