



StreamLine® Low Profile Steady Burning Light

Models LP3MI, LP3PI, LP3TI

COMPACT, ECONOMICAL AND FLEXIBLE

- Available in 24VDC and 120VAC
- T-mount, integrated 1/2-inch NPT pipe mount or 1/2-inch NPT male pipe mount
- Incandescent lamp included
- Five dome colors
- 15 watt incandescent lamp
- Screw-on lens
- Type 4X enclosure
- Optional wire guard
- UL and cUL Listed and CSA Certified

Federal Signal introduces the Model LP3I low profile steady burning light. The Type 4X light is available in five colors: Amber, Blue, Clear, Green, and Red.

The LP3I is offered in three mounting configurations. LP3PI features an integrated 1/2" NPT pipe mount. LP3MI features an integrated 1/2" NPT male pipe mount. The "T-mount" LP3TI has a popular 2-hole design for wall or flush mounting.

Both the LP3MI and LP3TI include a surface gasket to complete the Type 4X installation. All LP3I units feature a threaded screw-on lens. The LP3I comes in two voltages: 24VDC and 120VAC.

A 15 watt incandescent lamp is included with all units. The lamp features a standard double-contact bayonet base readily available when replacement is required.

Like all Streamline® products, the LP3I is designed with OEM applications in mind. It is economical, easy to install and attractive. Careful consideration has been given to the relationship between lamp shape and lens design for maximum light output.

When your application calls for a compact signal with unparalleled reliability, Federal Signal's Streamline products are the clear choice.

Model	Voltage	Power	Operating Current
LP3 ** I-024 *	24VDC	15 watt	0.67 amps
LP3 ** I-120 *	120VAC	15 watt	0.13 amps


** Indicates Mounting Style:

(S) Surface Mount, (P) Pipe Mount (T) T-Mount, or (M) Male Pipe Mount

* Indicates color: (A) Amber, (B) Blue, (C) Clear, (G) Green or (R) Red



STREAMLINE® LOW PROFILE STEADY BURN LIGHT (LP3MI/LP3PI/LP3TI)

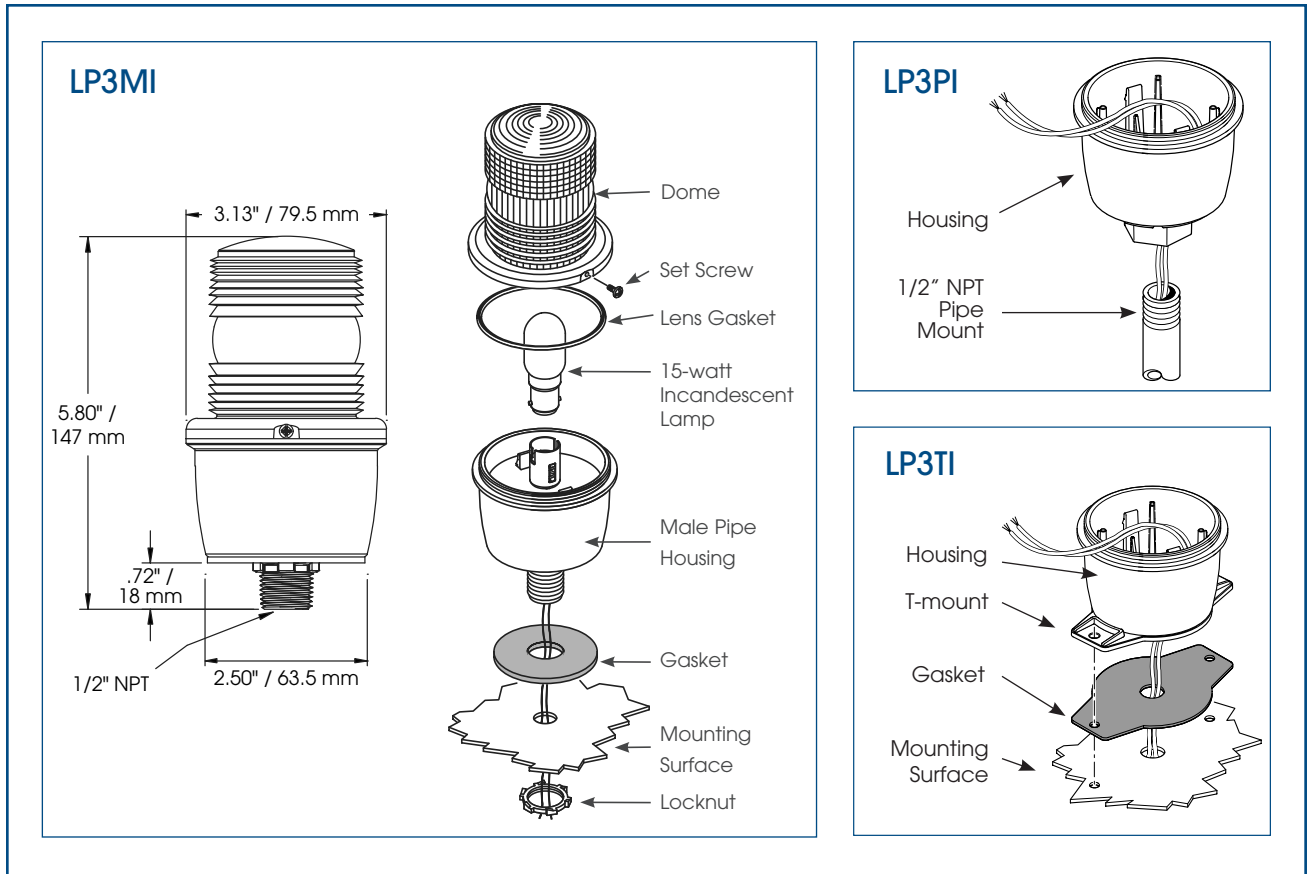

SPECIFICATIONS

Lamp Life:	2,000 Hours	2,000 Hours
Light Source:	Incandescent	Incandescent
Operating Temperature:	-31°F to 150°F	-35°C to 65°C
Net Weight:	7.3 oz.	206.96 g
Shipping Weight:	8.5 oz.	240.98 g
Diameter:	3.13"	7.95 cm
Height (from bottom):		
LP3PI	5.7"	14.48 cm
LP3MI	5.8"	14.7 cm
LP3TI	5.1"	12.95 cm

HOW TO ORDER

- Specify model, voltage and color
- Optional Accessories:
Wire Guard (LP3G) Compatible with S, T, and M mounts only
- Please refer to Model Number Index LP3I beginning on page 370

REPLACEMENT PARTS

<u>Description</u>	<u>Part Number</u>	<u>Description</u>	<u>Part Number</u>
Lens, Amber	K8589063A	Lamp, 120VAC	K8107194A
Lens, Blue	K8589063A-01	Lamp, 24VDC	K8107227A
Lens, Clear	K8589063A-02	Gasket, LP3TI	K8589012A
Lens, Green	K8589063A-03	Gasket, Lens	K8589013A
Lens, Red	K8589063A-04		