

Cole-Parmer®

Cole-Parmer® FEP Thermal-Resistant Rigid Tubing

Made of 100% virgin-grade fluorinated ethylene propylene (FEP), this tubing is perfect to use when chemically inert, thermal-resistant rigid tubing is needed. This tubing offers excellent resistance to a broad range of solvents, bases, and strong acids.


The nonstick property and low permeability help reduce the absorption/adsorption of fluids, minimizing the risk of fluid contamination. Optically clear tubing makes it easy to view your fluid for sight gauge and flow applications.



CERTIFICATION

FDA and USP Class VI compliant

FEP TUBING

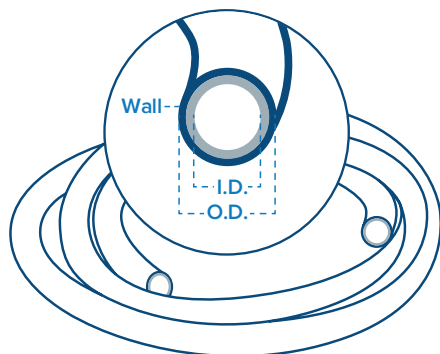

USA	+1.800.323.4340
	+1.847.549.7600
Canada	+1.800.363.5900
China	86.21.5109.9909
India	+1.800.266.1244

UK	+44 (0) 1480.272279
	+33 (0) 1.87.170142*
	+49 (0) 937.792030*
Italy	+39.02.84349215
All others	+1.847.549.7600

APPLICATIONS

- Perfect for transferring high-purity chemicals in semiconductor manufacturing and pharmaceutical processing
- Ideal for general-purpose, laboratory, and single-use applications

FEATURES/BENEFITS

- Excellent chemical and thermal resistance withstanding temperatures up to 204 °C (400 °F)
- Great optical clarity—easily view your sample in use
- Rigid tubing with a 60 Shore D durometer
- Sterilize by autoclave, EtO, and chemical sterilant
- Free technical application support available to assist with tubing selection

Cole-Parmer®

coleparmer.com

*Inquiries from Germany and France are now handled in our St. Neots office by native-speaking experts.

Specification and Ordering Table

Dimensions: in. (mm)			Item Number	Reel Length (ft)
Tubing ID	Tubing OD	Wall		
1/32" (0.8)	1/16" (1.6)	1/32" (0.8)	50136-83	50
1/16" (1.6)	1/8" (3.2)	1/32" (0.8)	50119-15	50
3/32" (2.4)	5/32" (4)	1/32" (0.8)	50119-16	50
1/8" (3.2)	3/16" (4.8)	1/32" (0.8)	50119-17	50
1/8" (3.2)	1/4" (6.4)	1/16" (1.6)	50119-18	50
5/32" (4)	1/4" (6.4)	3/64" (1.2)	50119-20	50
3/16" (4.8)	1/4" (6.4)	1/32" (0.8)	50119-19	50
7/16" (11)	1/2" (12.7)	1/32" (0.8)	50119-23	50
1/2" (12.7)	9/16" (14.3)	1/32" (0.8)	50119-24	50