

## Cole-Parmer® Flexicon Style Filling Needles 316L Stainless Steel



These single-use filling needles come ready to use—simply open, sterilize, and place in a filling machine. Needles go through meticulous quality control checks to ensure consistent, repeatable performance across batches. Needles are constructed of high-quality 316L stainless steel with a polycarbonate housing in an oil- and adhesive-free manufacturing process, minimizing introduction of foreign particles into the filling environment.



### CERTIFICATION

USP Class VI and RoHS compliant

**WARNING:** This product is not approved or intended for, and should not be used for, medical, clinical, surgical, or other patient-oriented applications.

### APPLICATIONS

- Perfect for final-fill dosing, cell and gene therapy, and drug substance aliquoting
- Ideal for general-purpose, laboratory, and single-use applications

### FEATURES/BENEFITS

- Ensure accurate dosing while minimizing waste
- Made from premium 316L stainless steel with a polycarbonate housing
- 70% IPA cleaned in ISO Class 7 cleanroom prior to double-bagging
- Needle straightness of <2mm/M for high-speed filling
- Sterilize via autoclave or gamma radiation (50 kGy)
- Latex and phthalate free


USA	+1.800.323.4340
	+1.847.549.7600
Canada	+1.800.363.5900
China	+86.21.5109.9909
India	+1.800.266.1244

UK	+44 (0) 1480.272279
	+33 (0) 1.87.170142*
	+49 (0) 937.792030*
Italy	+39.02.84349215
All others	+1.847.549.7600

# Cole-Parmer®

[coleparmer.com](http://coleparmer.com)

\*Inquiries from Germany and France are now handled in our St. Neots office by native-speaking experts.

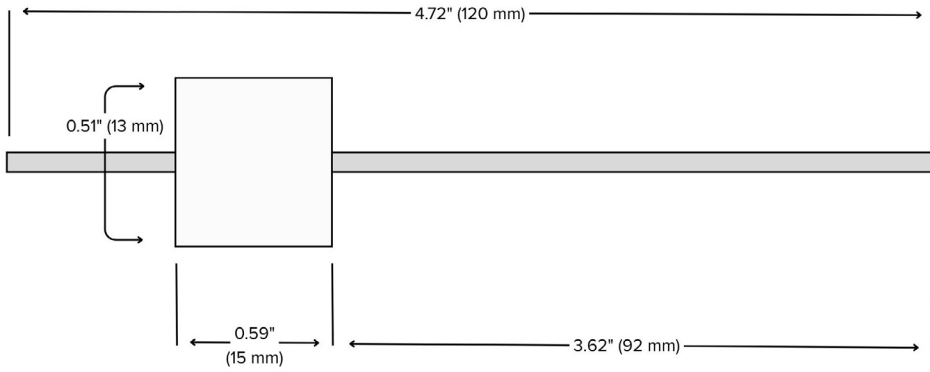

### Specification and Ordering Table

Dimensions: in. (mm)		For Dose Tube ID: in. (mm)	Item Number	Pack Size
Needle ID	Needle OD			
0.024" (0.6)	0.039" (1)	1/32" (0.8)	<a href="#">50142-36</a>	1
0.039" (1)	0.059" (1.5)	3/64" (1.2)	<a href="#">50142-37</a>	1
0.063" (1.6)	0.083" (2.1)	1/16" (1.6)	<a href="#">50142-38</a>	1
0.118" (3)	0.15" (3.8)	1/8" (3.2)	<a href="#">50142-39</a>	1
0.177" (4.5)	0.217" (5.5)	3/16" (4.8)	<a href="#">50142-40</a>	1
0.236" (6)	0.276" (7)	1/4" (6.4)	<a href="#">50142-41</a>	1